


LED tape KWP-GHD-1260-24 12.6 W/m, IP65

Ref. KWP-GHD-1260-24



Dimensions: Width [W]: 10 mm | Height [H]: 3 mm | Max run length [L]: 4 m | Cut every [C]: 33.3 mm | LED spacing [D]: 4.81 mm

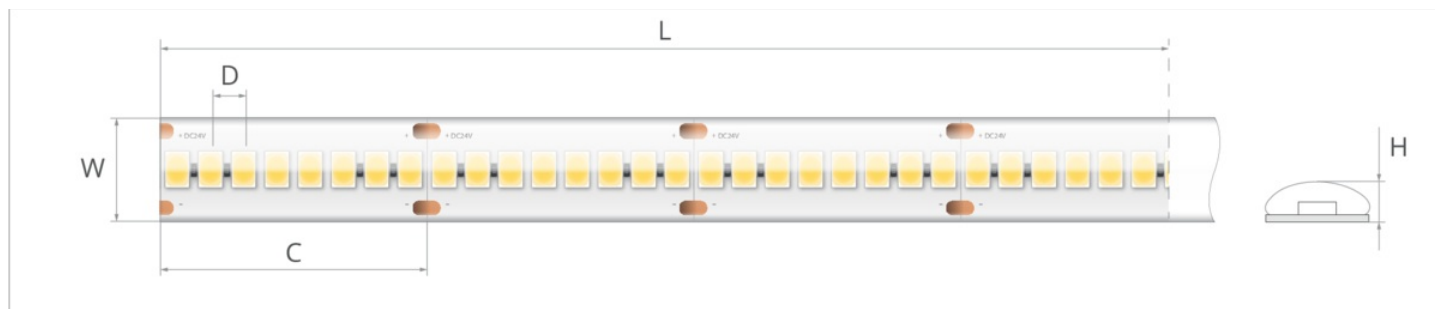

- High lighting efficacy
- High density diode placement
- Energy class: C
- For the construction of sealed lighting fixtures

TECHNICAL SPECIFICATIONS

IP protection rating	65
Sealing type	gel cover
CRI	90
LxBy	L80B50
Lifetime	75000 h
Input voltage	24 V DC
Power consumption	12.6 W/m
MacAdam's ellipse	3 SDCM
Number of LEDs per 1 m	240
Number of LEDs per cut section	7 pcs
Warranty [months]	48

Color temperature	Lumen output	Efficiency	Ref
2700 K	2015 lm/m	160 lm/W	KWP-GHD27-1260-24
3000 K	2080 lm/m	165 lm/W	KWP-GHD30-1260-24
4000 K	2190 lm/m	174 lm/W	KWP-GHD40-1260-24