



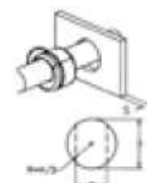

Pressacavi in nylon Nylon cable-glands

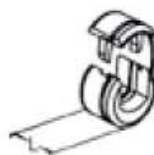

Articolo Type	Dimensione cavo Dimension cable Ø mm	S mm	H	W	L	Conf. pezzi Packing pcs.
BM 3622	4...4,5mm	1,6	12,7	11,45	11,1	1000
BM 3623	5,5...6,3mm	1,6	15,9	14	14,7	500
BM 1103	Pinza per l'inserimento del pressacavo/Pressure glands tool					

Materiale: Nylon (PA6.6) nero

Temperatura d'esercizio: 110°C

Pressacavo per la protezione dei conduttori su lamiere con spessore da 1,6 ÷ 2,6 mm

Di facile applicazione e di elevate caratteristiche meccaniche è particolarmente indicato per l'impiego su apparecchi di illuminazione e piccoli elettrodomestici

Material: Nylon (PA6.6) black

Exercise temperature: 110°C

By a simple pressure the cable-glands fix securely to panel with 1.6 to 2.6 mm thickness

Provide a strong mechanicals retention making it ideal for light and little electrodomestic apparatus



Articolo Type	A	B	C
BM M932	44,3	14,6	14,5

SUPPORTO FERMACAVO

Materiale: Nylon (PA 6.6) colore nero UL 94 - V2

Temperatura d'esercizio: 125°C

CABLE CLAMP

Material: Polyamid (PA 6.6) black color UL 94 - V2

Exercise temperature: 125°C