
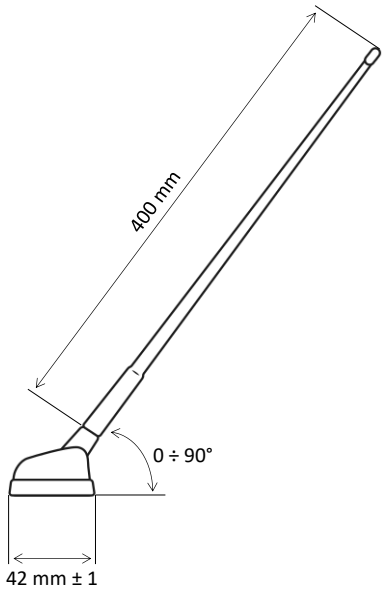
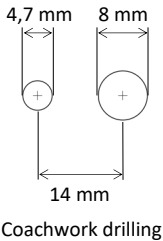


AM/FM PASSIVE ANTENNA WITH CABLE

GENERAL DESCRIPTION

AM/FM antenna with fiberglass rod and TE base for universal application.
Extension cable included.

DIMENSIONS

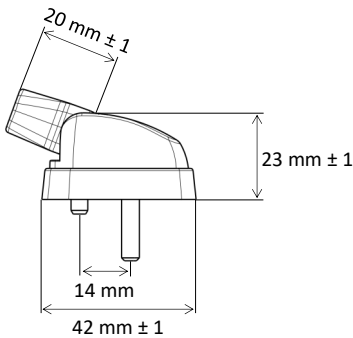

TECHNICAL DATA	AM/FM
Antenna type	Passive
Frequencies	525 - 1710 kHz 87,5 - 108 MHz
Rod type	Smooth
Rod lenght	400 mm
Rod thread	M6
Cable type	AR7
Cable lenght	2450 mm
Connector	DIN Male
Impedance	130 Ω
Mounting type	Universal
Mounting surface	Metal surface
IP grade	IP68

DISCLAIMER – Products, information, drawings, specifications and reference numbers (hereafter “contents”) discussed herein are for reference purposes only. All contents herein are provided on an “as is” basis, without warranties of any kind. The contents discussed herein remain the sole and exclusive property of MTA S.p.A. and shall not be copied, translated in whole or in part without MTA S.p.A. prior written consent. No license of any patent, copyright, mask work, trademark or any other intellectual property right is granted under this document, by implication, estoppel or otherwise. Contents may be modified and changed by MTA S.p.A. without any notice. For updates or additional information about MTA products, please contact your nearest MTA office. All brand names, trademarks and registered trademarks belong to their respective owners.