

LogiLink®




USB-C 3.2 Gen 1 Dual Bay RGB Lighting Docking Station For 2.5" & 3.5" SATA HDD/SSD

Art. No.: QP0036

Portable external storage with one key offline clone, file backup is never easier!

Features:


- » Compliant with USB 3.2 Gen 1 specification, data transfer up to 5 Gbps
- » Support 2.5" and 3.5" SATA III HDD/SDD, capacity up to 10 TB
- » Compatible with Thunderbolt 3/4
- » One-key offline cloning saves energy and time by eliminating the need for a laptop or computer
- » Dynamic RGB lighting
- » Silent operation. Safe and stable for data transfer
- » Support USB Hot Plug and Plug & Play
- » 12 V/3 A (36 W) power supply included
- » Compatible with Windows, Mac OS and Linux

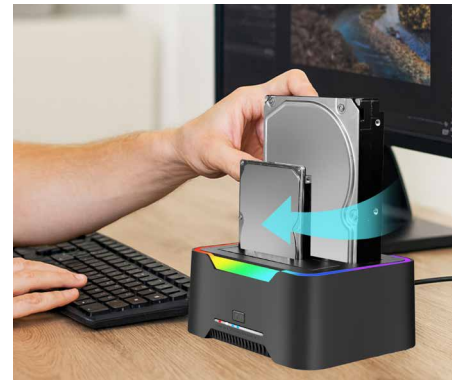

Easy backup from computer to HDD or
HDD to HDD without computer



RGB lighting

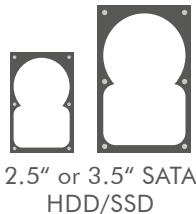

2.5" or 3.5" SATA
HDD/SSD



Offline Clone
Button




USB-C connection to
computer/laptop

External Power Supply



2-in-1 USB-C to
USB-C/USB-A cable

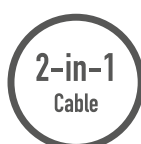


Specification:

USB Version	USB 3.2 Gen 1
Connection	USB-C female
Interface	SATA
SATA Version	SATA I/II/III
Data Transfer Rate	Up to 5 Gbps
Thunderbolt Compatibility	3 & 4
LED Indication	LED for power and activity
SATA Slot Support Type	2.5"/3.5" HDD/SSD
Supporting Hard Drive Capacity	Up to 10 TB
Offline Cloning Support	Yes
RGB Lighting	Yes
Hot Plug & Plug & Play	Yes
Power & RGB On/Off Switch:	Yes
Power By	DC 12 V/3 A (36 W)
Standby Power Consumption	5 W
Compatibility	Windows, Mac OS 10.0 or above and Linux
Housing Material	ABS
Color	Black
Operating Temperature	-10–60°C
Operating Humidity	25–60% RH (no condensation)
Dimensions	14.3 x 11.6 x 6 cm
Weight	282 g
Cable Length	100 cm

Specification of External Power Supply:

Input Voltage	100–240 V, 50/60 Hz 1.2 A max.
Output Power	12 V/3 A, 36 W
DC Plug	5.5 x 2.5 mm
Dimensions	79 x 43.8 x 67.9 mm
Cable Length	1.5 m
Weight	106 g

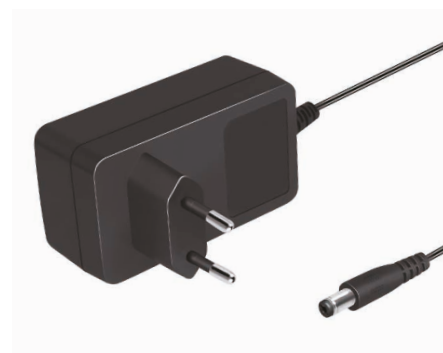

Package Contents:

- » 1x USB-C Docking Station
- » 1x 2-in-1 USB-A/USB-C to USB-C Cable
- » 1x Power Supply
- » 1x User Manual

Package Information:

- » Packing Dimension: 226 x 140 x 70 mm
- » Packing Weight: 0.57 kg
- » Carton Dimension: 370 x 295 x 240 mm
- » Carton Q'ty: 10 pcs
- » Carton Weight: 6.2 kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

