


42LMP

combination wrenches, open and offset ring ends, long series, bright chrome-plated

	Art.	M mm	M1 mm	L mm	H mm	Ø mm	S mm	S1 mm	α °	g
000420508	42LMP 8	8	8	148	17,1	12,8	6,1	4,7	15	29
000420510	42LMP 10	10	10	172	22,1	16,5	7,6	5,5	15	58
000420512	42LMP 12	12	12	197	26,8	18,6	8,6	5,9	15	78
000420513	42LMP 13	13	13	207	27,7	19,8	9	6,4	15	87
000420514	42LMP 14	14	14	223	31	22,2	9,4	7,0	15	122
000420515	42LMP 15	15	15	233	33	23,2	10,1	7,3	15	135
000420517	42LMP 17	17	17	261	37,6	26,5	11,4	8,4	15	184
000420518	42LMP 18	18	18	270	39,4	27,6	11,6	8,7	15	196
000420519	42LMP 19	19	19	280	41,8	28,2	12,5	9,2	15	214
000420521	42LMP 21	21	21	301	45,2	32,5	13,4	9,6	15	287
000420522	42LMP 22	22	22	318	47,7	33,2	14,5	9,9	15	345
000420524	42LMP 24	24	24	338	52	35,5	15,2	10,5	15	422
000420527	42LMP 27	27	27	376	58,3	40	17,4	12,1	15	575
000420530	42LMP 30	30	30	412	60,5	42,4	18,5	12,8	15	674
000420532	42LMP 32	32	32	435	66	47	19,3	13,3	15	848

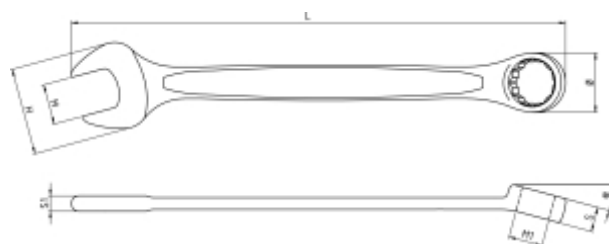

Scan the QR Code to access the web tab

Specs, media and documentation in one click.

