




DIN 6797 A

Norma ritirata

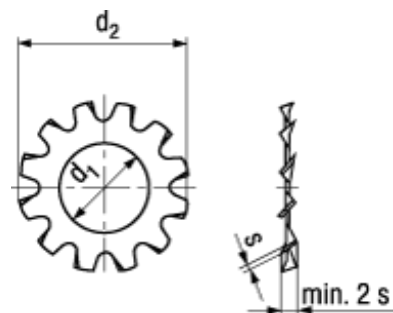

BN 2842

Rosette elastiche dentate

forma A con dentatura esterna

INOX A2

- ~UNI 8841 A
- ~CSN 021744

Article#		d ₁ min.	d ₂ max.	s
1486780	M2,5	2,7	5,5	0,4
1486799	M3	3,2	6	0,4
1486802	M4	4,3	8	0,5
1486810	M5	5,3	10	0,6
1486829	M6	6,4	11	0,7
1486837	M8	8,4	15	0,8
1486845	M10	10,5	18	0,9
1486853	M12	13	20,5	1
1486888	M16	17	26	1,2