

# ESD Lab Coats 1/2 Length

# ESD Lab Coats 3/4 Length



64% polyester, 32% cotton and 4% conductive fiber

Weight: 135g/m<sup>2</sup>

Static dissipative carbon loaded yarn in 4mm grid

Hidden fastening with metal snap-fasteners on front and cuffs

ESD symbol on left chest pocket

Unisex sizes: XS - 3XL (others on request)

Custom logos and staff names on request

| Size | Black       | White       | Grey        | Light Blue  |
|------|-------------|-------------|-------------|-------------|
| XS   | STC11230301 | STC11240401 | STC11210101 | STC11222221 |
| S    | STC11230302 | STC11240402 | STC11210102 | STC11222222 |
| M    | STC11230303 | STC11240403 | STC11210103 | STC11222223 |
| L    | STC11230304 | STC11240404 | STC11210104 | STC11222224 |
| XL   | STC11230305 | STC11240405 | STC11210105 | STC11222225 |
| 2XL  | STC11230306 | STC11240406 | STC11210106 | STC11222226 |
| 3XL  | STC11230307 | STC11240407 | STC11210107 | STC11222227 |

64% polyester, 32% cotton and 4% conductive fiber

Weight: 135g/m<sup>2</sup>

Static dissipative carbon loaded yarn in 4mm grid


Hidden fastening with metal snap-fasteners on front and cuffs

ESD symbol on left chest pocket

Unisex sizes: XS - 3XL (others on request)

Custom logos and staff names on request

| Size | Light Blue  | White       | Grey        | Black       |
|------|-------------|-------------|-------------|-------------|
| XS   | STC12222221 | STC12240401 | STC12210101 | STC12230301 |
| S    | STC12222222 | STC12240402 | STC12210102 | STC12230302 |
| M    | STC12222223 | STC12240403 | STC12210103 | STC12230303 |
| L    | STC12222224 | STC12240404 | STC12210104 | STC12230304 |
| XL   | STC12222225 | STC12240405 | STC12210105 | STC12230305 |
| 2XL  | STC12222226 | STC12240406 | STC12210106 | STC12230306 |
| 3XL  | STC12222227 | STC12240407 | STC12210107 | STC12230307 |

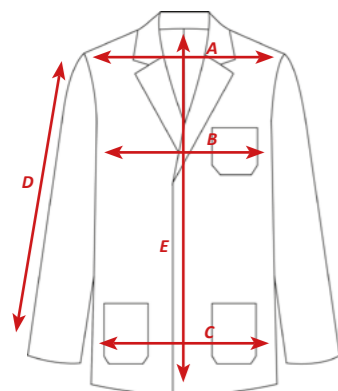


Resistivity point-point (Rp): 10<sup>6</sup>- 10<sup>7</sup>Ohms  
Decay time: < 2 seconds  
Conforms to current ESD Standards;  
IEC61340-5-1 & ANSI/ESD S20.20

| Size | A  | B  | C  | D  | E  |
|------|----|----|----|----|----|
| XS   | 48 | 54 | 56 | 54 | 80 |
| S    | 50 | 56 | 58 | 57 | 82 |
| M    | 52 | 58 | 60 | 59 | 84 |
| L    | 54 | 60 | 62 | 61 | 86 |
| XL   | 56 | 62 | 64 | 63 | 88 |
| 2XL  | 58 | 64 | 66 | 65 | 90 |
| 3XL  | 60 | 66 | 68 | 67 | 92 |

The electrical properties are retained, even after 50 industrial washes.

- Wash at maximum 60°C
- Ironing at maximum 110°C
- Do not bleach
- Do not dry clean
- Do not tumble dry
- Do not use fabric softeners

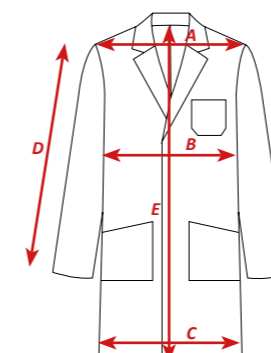

Resistivity point-point (Rp): 10<sup>6</sup>- 10<sup>7</sup>Ohms  
Decay time: < 2 seconds  
Conforms to current ESD Standards;  
IEC61340-5-1 & ANSI/ESD S20.20

| Size | A  | B  | C  | D  | E   |
|------|----|----|----|----|-----|
| XS   | 47 | 53 | 53 | 52 | 100 |
| S    | 48 | 55 | 55 | 53 | 102 |
| M    | 50 | 57 | 57 | 57 | 104 |
| L    | 52 | 58 | 60 | 59 | 106 |
| XL   | 54 | 60 | 61 | 61 | 107 |
| 2XL  | 56 | 63 | 63 | 63 | 108 |
| 3XL  | 58 | 64 | 65 | 65 | 110 |

The electrical properties are retained, even after 50 industrial washes.

- Wash at maximum 60°C
- Ironing at maximum 110°C
- Do not bleach
- Do not dry clean
- Do not tumble dry
- Do not use fabric softeners