


Network Wall Outlet 2 Port Cat.6A LSA

Description

This surface mounted box by Delock can be used as a network outlet on the wall or in enclosures.

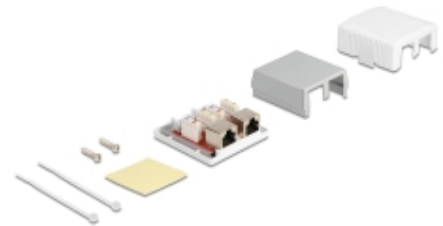

Item no. 86197

EAN: 4043619861972

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - external:
 - 2 x RJ45 jack
 - internal:
 - 2 x LSA block
- Cable routing 180°
- Shielded (STP)
- Cat.6A specification
- TIA-568A/B pinout
- Cable diameter up to 0.644 mm (22 - 26 AWG)
- Colour: white
- Dimensions (LxWxH): ca. 61 x 59 x 29.5 mm

System requirements

- Punch down tool

Package content

- Modular Wall Outlet

- Adhesive pad, 45 x 45 mm
- 3 x screw
- 2 x zip-tie

Images



General

Suitable for conductor gauge:	22 - 26 AWG
Mounting type:	wall

Interface

External:	2 x RJ45 jack
Internal:	2 x LSA block

Technical characteristics

Category:	Cat.6A
-----------	--------

Physical characteristics

Housing colour:	white
Shielding:	shielded
Length:	61 mm
Width:	59 mm
Height:	29.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

