


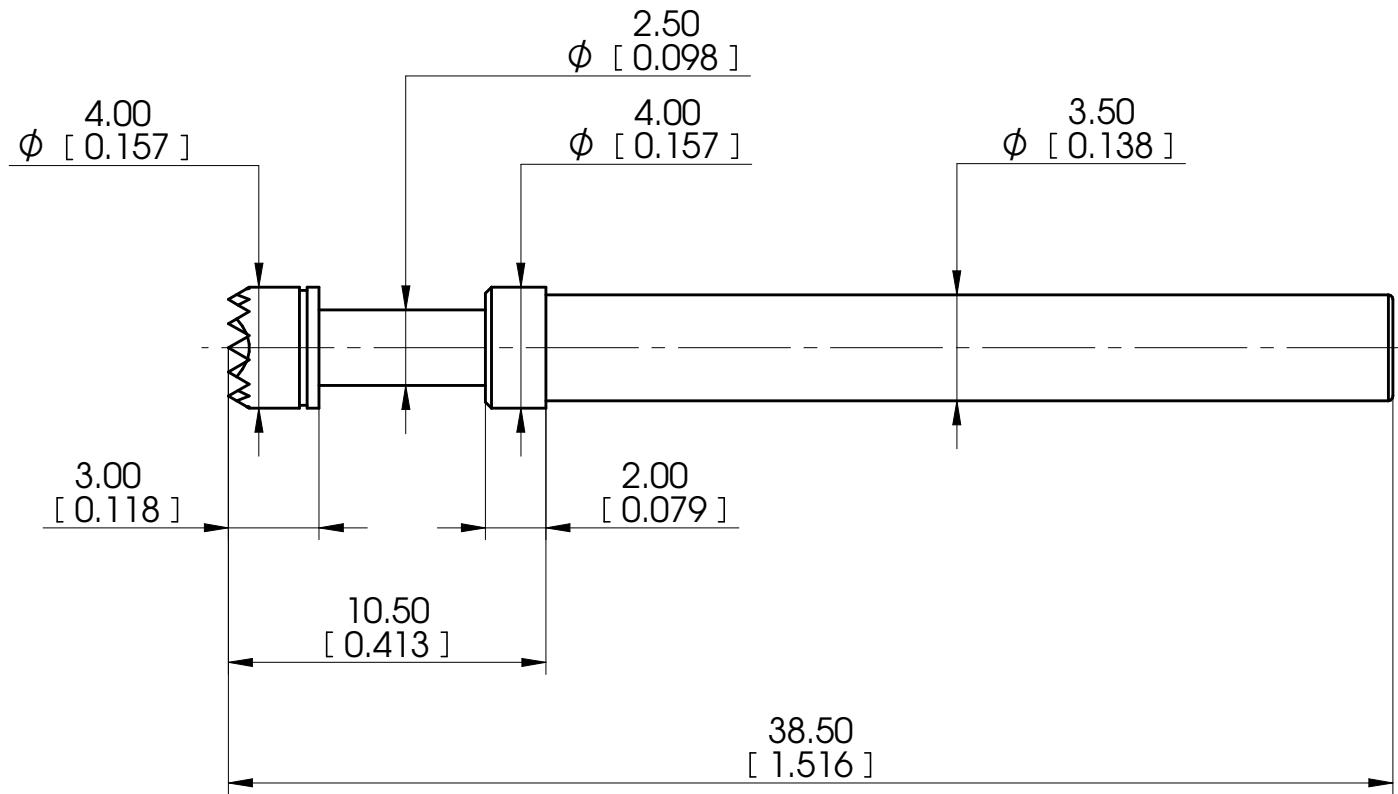

mm [inch]

HC2000 CG04 L

Minimum centers: 5.08 (.200)
 Full travel: 5.50 (.217)
 Working travel: 4.40 (.173)
 Current rating: 50 A (for short loads up to 80 A)
 Probe resistance: max 10 mΩ
 Plunger material: BeCu - Gold Plated
 Barrel material: Brass - Gold Plated
 Spring material: Stainless Steel

Operating Temperature: -40 °C up to +250 °C
 (-40 °F up to +482 °F)

Spring force at working stroke: 3 N (10.8 oz)



© COPYRIGHT 2018
 EQUIP-TEST KFT.
 ALL RIGHTS RESERVED

This drawing, model, intellectual
 product belongs to Equip-Test Kft.
 Forwarding it to 3rd. party, copying it
 or using for any other purpose
 without the written approval of
 Equip-Test Kft., could entail to legal
 and criminal procedure!

	Name	Date
Designed	V.Z.	2018.10.05.
Drawed		
Checked		

Note

Catalog Item:

HC2000 CG04 L

Drawing No.:



A4

SHEET 1 OF 1

