

USB Docking Station Dual DisplayPort 4K / USB 3.2 / LAN / Audio (Displaylink)

Description

This docking station by Delock can be connected to a computer with a **USB-C™** or **USB Type-A** port and provides a variety of interfaces. **Two monitors** can be operated **simultaneously at the DisplayPort output ports**. Six built-in USB 3.2 Gen 1 ports allow the use of peripherals, and connections for microphone and speaker and Gigabit network complete the features.

4K 60 Hz UHD resolution

Ultra-HD (4K) resolution is possible when using only one monitor and also when using both DisplayPort outputs at the same time. There is no DisplayPort Alternate Mode support required.

Extended screen by Displaylink

Due to the Displaylink graphics chipset it is possible to use **mirrored and extended screen functions** on Windows and Mac OS operating systems.



Item no. 87728

EAN: 4043619877287

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - front side:
 - 1 x SuperSpeed USB 5 Gbps (USB 3.2 Gen 1) Type-A female
 - 1 x SuperSpeed USB 5 Gbps (USB 3.2 Gen 1) Type-A female - Battery Charging specification BC1.2
 - 1 x microphone 3.5 mm stereo jack
 - 1 x speaker 3.5 mm stereo jack
 - back side:
 - 4 x SuperSpeed USB 5 Gbps (USB 3.2 Gen 1) Type-A female
 - 2 x DisplayPort female
 - 1 x Gigabit LAN 10/100/1000 Mbps RJ45 jack
 - 1 x SuperSpeed USB 5 Gbps (USB 3.2 Gen 1) Type-B female
 - 1 x DC 20 V power connector
- Maximum resolution (depending on the system and the connected hardware):
 - Single display: up to 3840 x 2160 @ 60 Hz
 - Dual display: up to 3840 x 2160 @ 60 Hz
- Transmission of audio and video signals
- Functions: Mirrored or Extended

- 1 x On / Off switch
 - Colour: black
 - Dimensions without stand (LxWxH): ca. 190 x 78 x 38 mm
-

Power supply specification

- Wall power supply
 - Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 1.3 A
 - Output: 20 V / 2.25 A
 - Ground outside, plus inside
 - Dimensions:
 - inside: \varnothing ca. 1.7 mm
 - outside: \varnothing ca. 4.75 mm
 - length: ca. 9.5 mm
-


System requirements

- Mac OS 12.0.1 or above
 - Windows 8.1/8.1-64/10/10-64/11
 - PC or laptop with a free USB Type-A port or
 - PC or laptop with a free USB Type-C™ or Thunderbolt™ 3 port
-

Package content

- USB docking station
- Cable USB Type-A male to Type-B male, length ca. 1 m
- Cable USB-C™ male to USB Type-B male, length ca. 1 m
- Power supply
- User manual

Images

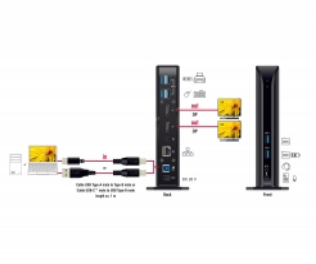

General

Function:	mirror and extend
Supported operating system:	Windows 10 32-Bit Windows 10 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows 11 Mac OS 12.0.1 or above

Technical characteristics

Maximum screen resolution:	3840 x 2160 @ 60 Hz
----------------------------	---------------------

Physical characteristics

Colour:	black
---------	-------

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de