

TIE10 SoftGuard

Soft Cable Ties
Black


UV-RESISTANT

HALOGEN-FREE

UL 94 V-2

ROHS COMPLIANT

CE

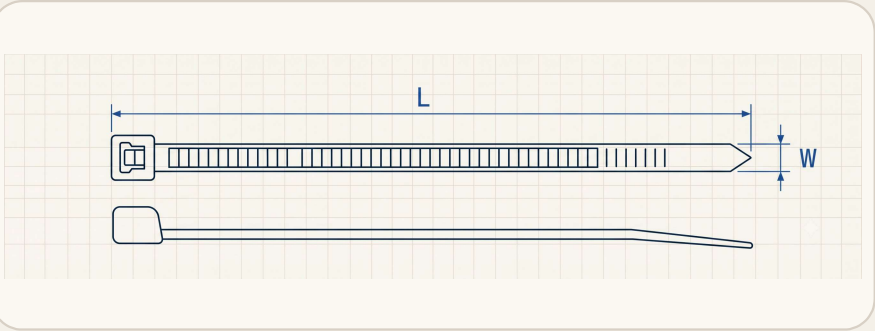

Technical specification

Material	Polyamide 6.6 + 1% carbon black
Colour	Black
Flammability	UL 94 V-2
Halogen-free	Yes
UV exposure	Resistant <i>suitable for outdoor use</i>
Moisture absorption	2.7% at 23 °C and 50% R.H.
Working temperature	-40 °C to +85 °C
Installation temperature	-10 °C to +60 °C
Resistant to	Aromatic solvents, oils, greases and derivatives
Limited resistance	Acids
Not resistant to	Phenols and chlorinated solvents

Range & item codes

ITEM CODE	SIZE	W (MM)	L (MM)	MAX Ø (MM)	N	KGf	PCS/PACK	PCS/CARTON
TT3.3X200B	3.3X200 mm	3.3	200	Ø50	167	17	100	12,000
TT3.3X250B	3.3X250 mm	3.3	250	Ø65	167	17	100	9,000
TT3.3X300B	3.3X300 mm	3.3	300	Ø80	167	17	100	8,000
TT4.3X200B	4.3X200 mm	4.3	200	Ø50	206	21	100	9,000
TT4.3X300B	4.3X300 mm	4.3	300	Ø80	206	21	100	6,000
TT4.3X400B	4.3X400 mm	4.3	400	Ø105	206	21	100	5,500

N / kgf = minimum loop tensile strength.